


Note:
- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:
CAD32UD

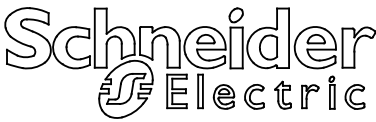

Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 8773425173
Email: CCC@us.schneider-electric.com

Rating: A600, Q600 10A
UL File/CCN: E164862 / NKCR
CSA File: LR43364 3211 03
Meets Standards: IEC 60647-5
Weight: 1.28 lb (0.58 kg)
Termination Method: Screw Clamp
Wire Size: #10 - #18 AWG
Terminal torque: 15 lb-in (1.7 Nm)
Mounting Hwd.: 35mm DIN Rail, #8 screw

Technical Information:

Specification:	
Description	TeSys D IEC Control Relay - 3NO,2NC - Vdc Coil
Type	TeSys D IEC Control Relay - 3NO,2NC - 250Vdc Coil
Voltages Code:	UD at 250Vdc
Coil Consumption:	Inrush 5.4 W Sealed 5.4 W