

# Wilco Rowco P Series

## Installation Instructions

Insulated Plug 32 A, 250 V / 500 V  
3, 4 and 5 Pin models

# CLIPSAL®

by **Schneider Electric**

### For your safety




#### HAZARD OF ELECTRIC SHOCK

- This product must be installed and serviced by appropriately qualified and/or licenced electrical personnel.
- Isolate the electrical supply before doing any work on this product.
- Ensure that the product has been correctly installed and tested for safe operation before reconnecting the electrical supply.


**Failure to follow these instructions will result in death or serious injury.**

### Installation

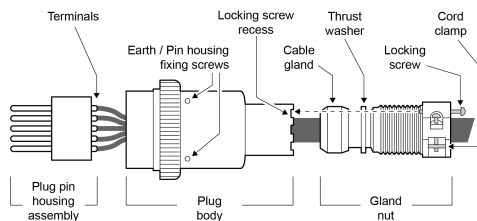

- ① Unscrew gland nut with complete gland assembly intact and loosen cord clamp.
- ② Remove earth / pin housing fixing screws from plug body.
- ③ Remove plug pin housing assembly from plug body.
- ④ Strip flexible cord, then pass through gland nut, cable gland and plug body.

 Stripping detail



- ⑤ Place appropriate conductors into plug pin housing assembly terminals and tighten screws to secure bared conductors and ensure good electrical contact.
- ⑥ Check Earth is connected to E terminal.
- ⑦ Pull excess cord in plug cover until pin housing assembly seats itself in plug body.

### Re-assembly

- ① Replace Earth and two fixing screws through plug body into plug pin housing assembly.
- ② Screw gland nut tight to ensure IP rating is maintained.
- ③ To lock gland nut in place, terminate locking screw into recess provided.
- ④ Tighten clamp onto cord.
- ⑤ Check earth screw is in place through plug body into earth pin.
- ⑥ Check earthing continuity with meter from earth pin to plug body.

Cat no	Desc	Max cable OD	Min cable ID	Alt entry thread form
P132	3 Pin 32 A, 250 V			
P432	4 Pin 32 A, 500 V	16.5 mm	11 mm	M32 x 1.5 mm
P532	5 Pin 32 A, 500 V			

**Note:** This product is designed to effectively clamp and seal on cable outside diameters listed above. Other devices, such as glands, flexible conduit adaptors, etc, may be used and will need to have the thread form as shown, to suit the product.

### Customer Care

#### Warranty information

We warrant this product for 3 years—visit <https://www.schneider-electric.com.au/en/about-us/legal/terms-and-conditions.jsp> for details.

Our goods also come with guarantees that cannot be excluded under the Australian Consumer Law. You are entitled to a replacement or refund for a major failure and compensation for any other reasonably foreseeable loss or damage. You are also entitled to have the goods repaired or replaced if the goods fail to be of acceptable quality and the failure does not amount to a major failure.

#### Schneider Electric (Australia) Pty Ltd

Customer Care: 13 73 28

e: [customer-care.au@schneider-electric.com](mailto:customer-care.au@schneider-electric.com)

[www.schneider-electric.com.au](https://www.schneider-electric.com.au)

Schneider Electric reserves the right to change specifications, modify designs and discontinue items without incurring obligation and whilst every effort is made to ensure that descriptions, specifications and other information in these instructions are correct, no warranty is given in respect thereof and the company shall not be liable for any error therein.

© Schneider Electric 2019

This material is copyright under Australian, New Zealand and international laws. Except as permitted under the relevant law, no part of this work may be reproduced by any process without prior written permission of and acknowledgment to Schneider Electric.

June 2019